


Structure

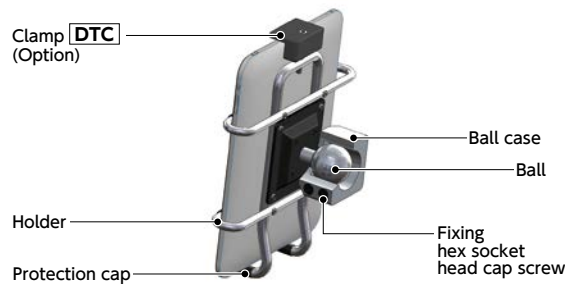

Material/Finish

	DTK-AF	DTK-AA / DTK-PB
Holder	SS400 Chrome Plating	
Protection Cap	Flexible PVC (lead-free)	
Ball Case	A6063 Anodized	
Ball	S45C Trivalent Chromate Treatment	
Fixing Hex Socket Head Cap Screw (M5×16mm)	SCM435 Ferrosoferric Oxide Film	
Fixing Plate	SS400 Electrostatic Coating	
Bracket	-	A6063 Anodized

Option

- By using the optional **DTC**, a tablet PC can be completely fixed.
- For cases where the mounting direction must be changed or taking out the tablet PC is prohibited.

Part Number	Mass (g)
DTC	70

Material / Finish

	DTC
Clamp	AC4C-F Electrostatic Coating
Clamping Screw	SUSXM7


Related Products

A 360° rotation type, spring type tablet PC holder **DTT** that can retain without bolt tightening is available.

➔ P.xxxx



- Tablet PC holder compatible with iPad*1.
*1: iPad is a trademark of Apple Inc. Compatible with iPad2, iPad3, and iPad4.
- This fixes a tablet PC to production equipment or test devices. Tablet PC can be mounted / unmounted easily just by inserting / removing it.
- Robust design. It has excellent durability.
- By tightening the fixing hex socket head cap screw, securely retain the angle after adjustment.
- Three types of Mounting System for Display® are available for different types of mounting surfaces.
 - For aluminum frame / For wall panel and sheet metal—**DTK-AF**
 - For aluminum frame end surface mounting—**DTK-AA**
 - For Round Pipe—**DTK-PB**
- This is suitable for checking the tablet PC screen while both hands are in use.
- For detailed dimensions of the holder, refer to **DTR**. ➔ P.xxxx
- The holder can be tilted by ±15° to any direction. It can also be rotated by 360°.

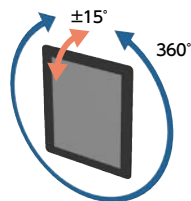

- We also produce Mounting System for Display® with special specifications compatible with tablet PCs of various sizes.
➔ P.xxxx



Application

Machine tool / Medical equipment / FPD production device / Semiconductor manufacturing device / Packing machine / Food machinery

Part number specification

DTK-AA-40

Product Code **1** **2**

Example of part number: DTK-AF-M8 / DTK-PB-40

- For aluminum frame / For wall panel and sheet metal

DTK-AF



Part Number	M*1 (d)	Mass (g)
DTK-AF-**	M4 (5)	1690
	M5 (6)	
	M6 (7)	
	M8 (9)	

*1: Mounting bolts are not supplied.

- For aluminum frame end surface mounting

DTK-AA



Part Number	B	Mass (g)
DTK-AA-40	40	1460

*1: Hex socket low head bolts (M8 × 16 mm) are provided.

- For Round Pipe

DTK-PB



Part Number	D	L1	L	Mass (g)
DTK-PB-**	28	114.5	138.5	1610
	30			1610
	34			1570
	40	118.5	146.5	1590
	42.7			1560

- Fixing rubber sheet is attached. Dimensional allowance of available round pipe is ±0.5 mm.

