




SNHP2S Hexagon Head Screws with Captive Washer

Easy operation **SUS** Stainless steel

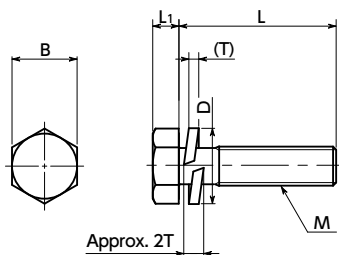

● Material/Finish



	SNHP2S
Screw Body	Equivalent to SUS304
Screw Body Strength Class	A2 - 50
Spring Washer	Equivalent to SUS304



- Hexagon head screws with captive washer compliant with JIS B 1187.
- Spring washers are integrated into the screws, preventing concerns about fallout issues. (Washer abbreviation: P=2)

Unit : mm

Part Number 1	M (Coarse)		L 2										D	L ₁	B	T (Approx.)	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch																
SNHP2S-M4	M4	0.7	8	10	12								7	2.8	7	1	1.6 - 1.9	20
SNHP2S-M5	M5	0.8		10	12	16	20						8.5	3.5	8	1.3	2.9 - 4.1	20
SNHP2S-M6	M6	1		10	12	16	20	25					11.5	4	10	1.5	4.9 - 7.6	20
SNHP2S-M8	M8	1.25				16	20	25	30	35			14.5	5.5	13	2	13 - 19	10
SNHP2S-M10	M10	1.5					20	25	30	35	40		17.5	7	17	2.5	25 - 35	10

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Part Number Specification

SNHP2S-M8-20

1

2

1 Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Not Available	Available / Add'l charge	Not Available