


# SNBS(INCH) Hex Socket Button Head Cap Screws - Inch Thread



WEB Selection Tool

WEB CAD Download

SUS Stainless steel

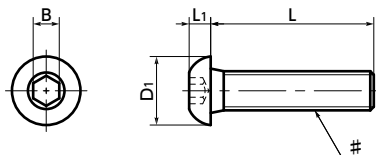

● Material/Finish

RoHS2 Compliant

SNBS(INCH)	
Main Body	Stainless Steel (Grade : A2)
Strength Class	A2-50

- Socket button head cap screws with inch thread.
- ANSI B18.3 compliance.
- Install and remove by using **SKH(INCH)** Specialty Key. → P.xxxx
- Also, products with special specifications such as dimensions, shapes, materials, surface treatments, cleanroom washing and special packaging are available. → P.xxxx



● Application

Equipment and devices using inch screw specifications

Unit : inch

Part Number	#	Nominal of Thread	L								D1	L1	B	Mass (g)	
			3 / 16	1 / 4	5 / 16	3 / 8	1 / 2								
SNBS-#4-40	No.4-40UNC										0.213	0.059	1 / 16	0.35 - 0.65	
SNBS-#5-40	No.5-40UNC			1 / 4		3 / 8	1 / 2				0.238	0.066	5 / 64	0.53 - 0.85	
SNBS-#6-32	No.6-32UNC			1 / 4	5 / 16	3 / 8	1 / 2	5 / 8	3 / 4		0.262	0.073	5 / 64	0.67 - 1.4	
SNBS-#8-32	No.8-32UNC			1 / 4		3 / 8	1 / 2	5 / 8	3 / 4		0.312	0.087	3 / 32	1.1 - 2.1	
SNBS-#10-24	No.10-24UNC			1 / 4		3 / 8	1 / 2	5 / 8	3 / 4	7 / 8	1	0.361	0.101	1 / 8	1.5 - 3.6
SNBS-#10-32	No.10-32UNF			1 / 4		3 / 8	1 / 2	5 / 8	3 / 4	7 / 8	1	0.361	0.101	1 / 8	1.5 - 3.8
SNBS-1 / 4-20	1/4-20UNC					3 / 8	1 / 2	5 / 8	3 / 4	7 / 8	1	0.437	0.132	5 / 32	3.3 - 6.4

● All dimensions are in inches.

Part Number	Qty*1 per pack
SNBS-#4-40	10
SNBS-#5-40	10
SNBS-#6-32	10
SNBS-#8-32	10
SNBS-#10-24	10
SNBS-#10-32	10
SNBS-1 / 4-20	10

\*1: Also sold separately from 1 piece up. → P.xxxx

● Part number specification

**SNBS-#4-40-1/4**



Order in number of packs.  
The minimum order is 1 piece. → P.xxxx

Individual Sales → P.xxxx	Cleanroom Wash & Packaging → P.xxxx	Screw Length Adjustment → P.xxxx	Vibration Resistant → P.xxxx	Modification process for captive use → P.xxxx
Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge