


- Installation example
Make a screw hole in the cover, then pass the knob thread through it. Even when the screw is removed from the frame, the knob does not fall out from the cover because the knob thread catches on the screw hole of the cover.

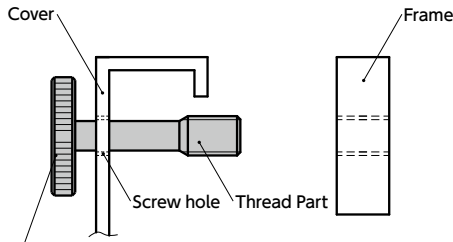

KUM-SC Captive Knurled Knob

- Captive type knurled knob. Prevents fall-off and loss of the knob.
- Foreign matter entry countermeasures in food processing machinery and so on, as well as CE marking support (→ P.xxxx).
- Flat type.

● Material/Finish ✔ RoHS2 Compliant

KUM-SC	
Main body	SWCH10R Buffing / Chrome Plating

- ⚠ Precautions for Use
Screw hole inner diameter on the cover side shall be at least the d1 dimension.
The cover thickness should be 0.8 mm or above.

- Part number specification

KUM-24-M6-20-SC

Product Code 1 2 3 Captive

Select a 3 thread length L from the dimension table.

Dimensions

Unit : mm

Part Number	D 1	M (Coarse)		Lm	H	d1	Mass (g)
		Nominal of Thread 2	Pitch				
KUM-12-M3-SC	12	M3	0.5	4	2.5	2.2	2 - 3
KUM-16-M4-SC	16	M4	0.7	5	3.5	3	6
KUM-20-M5-SC	20	M5	0.8	6	4	3.9	11 - 12
KUM-24-M6-SC	24	M6	1	8	5	4.6	20 - 21
KUM-30-M8-SC	30	M8	1.25	10	6	6.3	36 - 40
KUM-36-M10-SC	36	M10	1.5	12	8	8	69 - 77

Part Number	L (mm) 3					
	10	16	20	25	30	40
KUM-12-M3-SC	●	●				
KUM-16-M4-SC	●	●				
KUM-20-M5-SC	●	●	●			
KUM-24-M6-SC		●	●	●	●	
KUM-30-M8-SC		●	●	●	●	
KUM-36-M10-SC			●	●	●	●

Cleanroom Wash & Packaging → P.xxxx	Screw Combination → P.xxxx	Screw Length Adjustment → P.xxxx	Vibration Resistant → P.xxxx	Laser Marking → P.xxxx
Not Available	Not Available	Not Available	Not Available	Not Available