

● Material/Finish

RoHS2 Compliant

	<b>KUMS-SC</b>
Main Body	SUS304


**Precautions for Use**

Screw hole inner diameter on the cover side shall be at least  $d_1$ .

The cover thickness should be 0.8 mm or above.

- Captive type knurled knob. Prevents fall-off and loss of the knob.
- Foreign matter entry countermeasures in food processing machinery and so on, as well as CE marking support. (→ P.xxxx)
- Made of SUS304. For applications including food processing machinery, packaging machinery, etc., where corrosion resistance is called for.
- Flat type.
- Installation example

Make a screw hole in the cover, then pass the knob thread through it. Even when the screw is removed from the frame, the knob does not fall out from the cover because the knob thread catches on the screw hole of the cover.

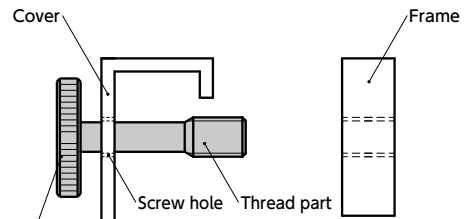

**KUMS-SC** Captive knurled knob

Unit : mm

## Dimensions

Part Number	D <span style="color: red;">1</span>	M (Coarse)		Lm	H	d <sub>1</sub>	Mass (g)
		Nominal of Thread <span style="color: red;">2</span>	Pitch				
<b>KUMS-12-M3-SC</b>	12	M3	0.5	4	2.5	2.2	2 - 3
<b>KUMS-16-M4-SC</b>	16	M4	0.7	5	3.5	3	6
<b>KUMS-20-M5-SC</b>	20	M5	0.8	6	4	3.9	11 - 12
<b>KUMS-24-M6-SC</b>	24	M6	1	8	5	4.6	20 - 21
<b>KUMS-30-M8-SC</b>	30	M8	1.25	10	6	6.3	36 - 40
<b>KUMS-36-M10-SC</b>	36	M10	1.5	12	8	8	69 - 77

Part Number	L (mm) <span style="color: red;">3</span>						
	10	16	20	25	30	40	
<b>KUMS-12-M3-SC</b>	●	●					
<b>KUMS-16-M4-SC</b>	●	●					
<b>KUMS-20-M5-SC</b>	●	●	●				
<b>KUMS-24-M6-SC</b>		●	●	●	●		
<b>KUMS-30-M8-SC</b>		●	●	●	●		
<b>KUMS-36-M10-SC</b>			●	●	●	●	

### ● Related Products

Different shapes of captive type knurled knobs are available.

**KNMS-SC** → P.xxxx

**KUM-SC** → P.xxxx



### ● Part number specification

## KUMS-24-M6-20-SC

Product Symbol 1 2 3 Captive

Select a 3 thread length L from the dimension table.

Cleanroom Wash & Packaging → P.xxxx	Screw Combination → P.xxxx	Screw Length Adjustment → P.xxxx	Vibration Resistant → P.xxxx	Laser Marking → P.xxxx
Available / Add'l charge	Not Available	Not Available	Not Available	Available / Add'l charge