




SRSHS Tamper - resistant Special Low Head Screw

WEB Selection Tool
 WEB CAD Download
 Protrusion
 Tamper Resistance
 SUS Stainless steel

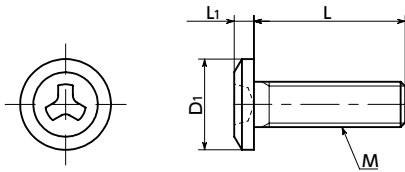

● Application

Dismantling equipment/device, tamper-resistance/anti-theft measures for outdoor facility/security measures/safety measures

● Material/Finish

RoHS2 Compliant

	SRSHS
Main unit	SUSXM7

- Tamper-Resistance screws, all with head height of 1.5 mm or less.
- It cannot be mounted or removed by normal tools. As well, because the head height is low, it is difficult to remove by grasping the head directly, leading to excellent anti-theft properties.
- The protrusion after mounting is minimal, leaving the external appearance unblemished.
- Use a dedicated bit **SRSHB** for mounting and removing.

Unit : mm



Part Number 1	M (Coarse)		L 2							D1	L1	Bit Part No.	Mass(g)
	Nominal of Thread	Pitch											
SRSHS-M2	M2	0.4	4	5	6	8				3	0.6	SRSHB-0	0.089 - 0.16
SRSHS-M2.5	M2.5	0.45	4	5	6	8				3.8	0.8	SRSHB-1	0.15 - 0.28
SRSHS-M3	M3	0.5			6	8	10	12		6	1.3	SRSHB-2	0.44 - 0.69
SRSHS-M4	M4	0.7				8	10	12	16	8	1.5	SRSHB-3	1.0 - 1.6

Part Number	Qty per pack*1
SRSHS-M2	10
SRSHS-M2.5	10
SRSHS-M3	20
SRSHS-M4	20

*1 : Also sold separately from 1 piece up.
→ P.xxxx

● Dedicated bit (Supports V6.3/U6.3 insert shapes) Unit : mm

Part Number 3	Applicable bolt	b	Qty per pack	Mass (g)
SRSHB-0	SRSHS-M2	2	1	6.4
SRSHB-1	SRSHS-M2.5	2	1	6.4
SRSHB-2	SRSHS-M3	3	1	13.8
SRSHB-3	SRSHS-M4	4	1	14.7

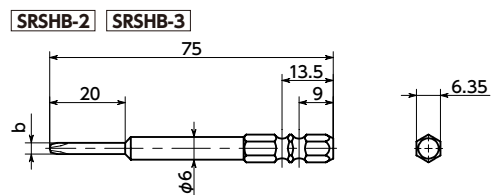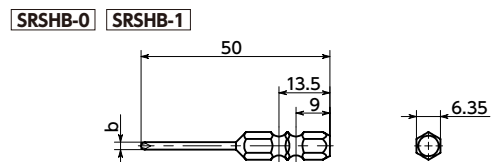

● Part number specification

SRSHS-M3 - 10 Tamper-resistant Special Low Head Bolts

1 2

SRSHB-2 Dedicated Bits

3

Place order by a bag.
Also sold separately from 1 piece up. → P.xxxx

Individual Sales → P.xxxx
 Cleanroom Wash & Packaging → P.xxxx
 Screw Length Adjustment → P.xxxx
 Vibration Resistant → P.xxxx
 Modification process for captive use → P.xxxx
 Available / Add'l charge Please feel free to contact us Male screw only/ Add'l charge Available / Add'l charge Available / Add'l charge