

SSHS-FT

Hex Socket Head Cap Screws with Special Low Profile - Full Thread




WEB Selection Tool

WEB CAD Download

Protrusion

Full Thread

SUS Stainless steel

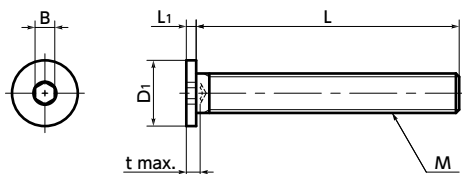

- Full thread socket head cap screws with special low Profile.
- The head height for all screws is 1.5 mm or less.
- Intended for reducing the size of devices and applications with limited overhead space.

● Application

Reducing the size of equipment and devices

● Material/Finish

RoHS2 Compliant

	SSHS-FT
Main Body	SUS304

Unit : mm

Part Number	M (Coarse)		L								D1	L1	B	t	Max. Torque (N·m)	Mass (g)
	Nominal of Thread	Pitch	16	20	25	30	40	50	60	70						
SSHS-M3-FT	M3	0.5	16	20	25	30	40	50			6	1.3	1.5	2	0.6	0.89 - 2.6
SSHS-M4-FT	M4	0.7		20	25	30	40	50	60		8	1.5	2	2.5	1.5	2 - 5
SSHS-M5-FT	M5	0.8				30	40	50	60	70	9	1.5	3	3	3.1	4.1 - 10
SSHS-M6-FT	M6	1					40	50	60	70	10	1.5	3	4	5.3	8.2 - 15
SSHS-M8-FT	M8	1.25					40	50	60	70	13	1.5	4	5	12	14 - 26
SSHS-M10-FT	M10	1.5					40	50	60	70	16	1.5	5	6	18	20 - 39

Part Number	Qty per pack
SSHS-M3-FT	1
SSHS-M4-FT	1
SSHS-M5-FT	1
SSHS-M6-FT	1
SSHS-M8-FT	1
SSHS-M10-FT	1

● Part number specification

SSHS - M8 - 60 - FT

Product Code 1 2 Product Code

Individual Sales → P.0000	Cleanroom Wash & Packaging → P.0000	Screw Length Adjustment → P.0000	Vibration Resistant → P.0000	Modification process for captive use → P.0000
1 unit in 1 bag	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge