

Material/Finish



	SEQ-TZB	SEQ-TBZ
Main Body	SWCH Trivalent Chromate Treatment (Silver)	SWCH Black Trivalent Chromate Treatment

Part number specification

SEQ-M3-8-TBZ

Cross Recessed Head Cap Screws with Extra Low Profile



SKQB-1

Dedicated Bits



Order in number of packs.

The minimum order quantity is 1 piece. ➔ P.xxxx

- Cross recessed head cap screws with extra low profile.
- For space-saving of equipment/devices and applications with limited overhead space.
- QuaStix *1 is used for the cross recess. By using a dedicated bit for QuaStix **SKQB**, the torque transmission is improved, preventing cam-out and damage to the cross recess. * 2
- * 1: QuaStix is a registered trademark of OSG Corporation.
- * 2: It can be mounted and removed with ordinary Phillips bits.
- Select from two surface treatment finish colors.

Application

Reducing the size of equipment and devices

SEQ-TZB Trivalent Chromate Treatment (Silver) **SEQ-TBZ** Black Trivalent Chromate Treatment

Unit : mm


Part Number	M	L	D1	L1	Bit Part No.	Max. Torque (N・m)	Mass (g)
SEQ-M3-TZB	M3	6 8 10 12	7	0.8	SKQB-1	0.7	0.39 - 0.64
SEQ-M4-TZB	M4	8 10 12 16	8	0.9	SKQB-2	1.8	0.8 - 1.4
SEQ-M3-TBZ	M3	6 8 10 12	7	0.8	SKQB-1	0.7	0.39 - 0.64
SEQ-M4-TBZ	M4	8 10 12 16	8	0.9	SKQB-2	1.8	0.8 - 1.4

Part Number	Qty per pack
SEQ-M3-TZB	50
SEQ-M4-TZB	50
SEQ-M3-TBZ	50
SEQ-M4-TBZ	50


- **SKQB** QuaStix dedicated bit
(Supports U6.3 insert shapes)

Part Number	Mass (g)	Qty per pack
SKQB-1	7.4	1
SKQB-2	17	1

SKQB-1

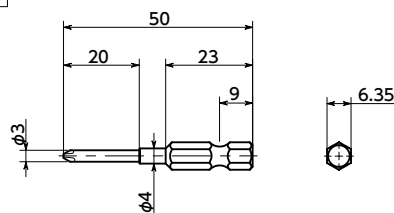

SKQB-2

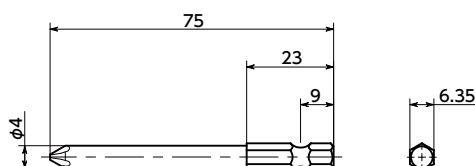

1 Individual Sales ➔ P.xxxx	Cleanroom Wash & Packaging ➔ P.xxxx	Screw Length Adjustment ➔ P.xxxx	Vibration Resistant ➔ P.xxxx	Modification process for captive use ➔ P.xxxx
Available / Add'l charge	Please feel free to contact us	Available / Add'l charge	Available / Add'l charge	Not Available