

SNF-SD / SNFS-SD

Cross Recessed Flat Head Machine Screws with Small Head



WEB Selection Tool


WEB CAD Download



Small Head

SUS

Stainless steel

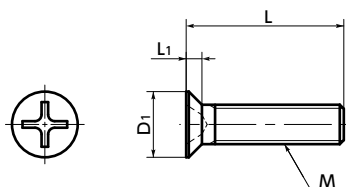

● Part number specification

SNF - M5 - 20 - SD - TZB

1

2

3

1

Order in number of packs.

Also sold separately from 1 piece up. ➔ P.xxxx



- Cross Recessed flat head machine screws with small head diameters. This makes it possible to reduce the spot facing diameters compared to standard flat head machine screws.
- Since the head height is lower than that of standard flat head screws. Suitable for connecting thin plates.

● Application

Reducing the size of equipment and devices

● Material/Finish 1

RoHS2 Compliant

	SNF-SD-TZB	SNFS-SD
Main Body	SWCH Trivalent Chromate Treatment	SUSXM7 (Equivalent to SUS304)

Unit : mm

SNF-SD-TZB	SNFS-SD	Common dimensions												
Steel - Trivalent Chromate Treatment	Stainless steel													
Part Number	Part Number	M	2	L	3						D1	L1	Mass (g)	
SNF-M3-SD-TZB		M3	5	6	8	10	12				5	1.3	0.41 - 0.69	
SNF-M4-SD-TZB	SNFS-M4-SD	M4		6	8	10	12	16			6	1.3	0.73 - 1.5	
SNF-M5-SD-TZB	SNFS-M5-SD	M5			8	10	12	16	20		8	1.8	1.7 - 3.1	
SNF-M6-SD-TZB	SNFS-M6-SD	M6				10	12	16	20	25	10	2.3	3.2 - 5.8	

SNF-SD-TZB Steel - Trivalent Chromate Treatment

Part Number	Qty*1 per pack
SNF-M3-SD-TZB	20
SNF-M4-SD-TZB	20
SNF-M5-SD-TZB	20
SNF-M6-SD-TZB	20

*1 : Also sold separately from 1 piece up. ➔ P.xxxx

SNFS-SD Stainless Steel

Part Number	Qty*1 per pack
SNFS-M4-SD	20
SNFS-M5-SD	20
SNFS-M6-SD	20

*1 : Also sold separately from 1 piece up. ➔ P.xxxx

1 Individual Sales ➔ P.xxxx	Cleanroom Wash & Packaging ➔ P.xxxx	Screw Length Adjustment ➔ P.xxxx	Vibration Resistant ➔ P.xxxx	Modification process for captive use ➔ P.xxxx
Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Not Available