




SFT/SFTS Hex Socket Pipe Plugs

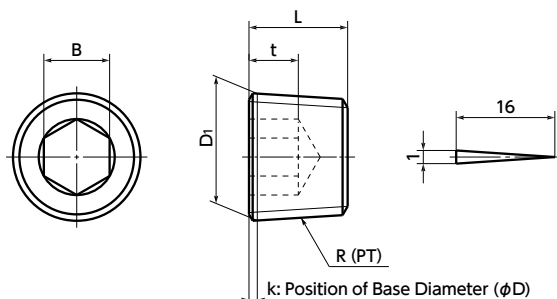

- Sinking type Pipe Taper Screw Plugs
- **SFT-PS** and **SFTS-PS** are precoated seal types which do not require sealing tape or sealant. This dramatically reduces work time. The sealing effect is also excellent.
- Precoated seals have excellent resistance to oil, gasoline, water, and heat.
- Application

Hydraulic equipment, pneumatic machinery and equipment, and general industrial machines

● Material/Finish

	SFT	SFT-PS	SFTS	SFTS-PS
Main Body	S45C (Hardness: 32 - 42 HRC) Ferrosoferric Oxide Film (Black)	S45C (Hardness: 32 - 42 HRC) Ferrosoferric Oxide Film (Black)	SUSXM7 (Equivalent to SUS304)	SUSXM7 (Equivalent to SUS304)

SFT SFT-PS Steel · Ferrosoferric Oxide Coating

Unit : mm

SFT No Seal	SFT-PS Pre-coat Seal	Common dimensions							Mass (g)	Qty*1 per pack
		Part Number ◀1	Part Number ◀1	R (PT) Nominal of Thread	D ₁	k	L	B		
SFT-0.5	SFT-0.5-PS	R1/16	7.723	0.45	6	4	3	2	10	
SFT-1	SFT-1-PS	R1/8	9.728	0.45	7	5	3.5	3	10	
SFT-2	SFT-2-PS	R1/4	13.157	0.7	8.9	6	4.5	6	10	
SFT-3	SFT-3-PS	R3/8	16.662	0.7	10	8	5	11	10	
SFT-4	SFT-4-PS	R1/2	20.955	0.9	12	10	6	21	5	

*1 : Also sold separately from 1 piece up. → P.xxxx

SFTS SFTS-PS Stainless Steel

Unit : mm

SFTS No Seal	SFTS-PS Pre-coat Seal	Common dimensions							Mass (g)	Qty per pack
		Part Number ◀1	Part Number ◀1	R (PT) Nominal of Thread	D ₁	k	L	B		
SFTS-0.5	SFTS-0.5-PS	R1/16	7.723	0.45	6	4	3	2	1	
SFTS-1	SFTS-1-PS	R1/8	9.728	0.45	7	5	3.5	3	1	
SFTS-2	SFTS-2-PS	R1/4	13.157	0.7	8.9	6	4.5	6	1	
SFTS-3	SFTS-3-PS	R3/8	16.662	0.7	10	8	5	11	1	
SFTS-4	SFTS-4-PS	R1/2	20.955	0.9	12	10	6	21	1	

● Part number specification

SFT-3-PS

◀1

Order in number of packs.

Also sold separately from 1 piece up. → P.xxxx

Individual Sales → P.xxxx	Cleanroom Wash & Packaging → P.xxxx	Screw Length Adjustment → P.xxxx	Vibration Resistant → P.xxxx	Modification process for captive use → P.xxxx
Available / Add'l charge	Not Available	Not Available	Not Available	Not Available