




SNFCS Hexagon Socket Countersunk Head Screws

SUS Stainless steel

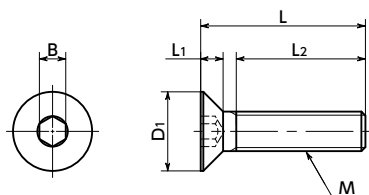

● Material/Finish



	SNFCS
Main Body	Stainless Steel (A2)
Strength Class	A2-50 or more

- Hex socket countersunk head screws conforming to JIS B 1194.

Unit : mm

Part Number	M (Coarse)		L													D1	L1	B	L2*1	Mass (g)	Qty per Pack
	Nominal of Thread	Pitch																			
SNFCS-M3	M3	0.5	5	6	8	10	12	16	20						6.72	1.86	2	Full Thread	0.34 - 0.94	20	
SNFCS-M4	M4	0.7			8	10	12	16	20	25	30				8.96	2.48	2.5	20 (L=30)	0.99 - 2.5	20	
SNFCS-M5	M5	0.8			8	10	12	16	20	25	30	35			11.2	3.1	3	22 (L=35)	1.8 - 4.8	20	
SNFCS-M6	M6	1				10	12	16	20	25	30	35	40		13.44	3.72	4	Full Thread	3.2 - 7.9	20	
SNFCS-M8	M8	1.25					12	16	20	25	30	35	40	45	50	17.92	4.96	5	Full Thread	7.2 - 18	10

*1 : If the "L" value is not in parentheses, the screw is full thread.

- When purchasing less volume than one full bag, a separate handling fee is charged. For details, see the Sold Separately Service.

● Part Number Specification

SNFCS-M3-8



1 Individual Sales	Cleanroom Wash & Packaging	Screw Length Adjustment	Vibration Resistant	Modification process for captive use
Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Not Available