

*: Check the A dimension based on the distance from the mounting surface to the top surface of the table and select accordingly.

- Gate type stoppers for linear guides with threaded holes (fine) machined. Mountable from rail top.
 - In combination with fine screw thread stopper bolts*1, fine adjustment of the screw-in depth is easy.
 - Supported rail sizes are 15 mm/20 mm/25 mm/30 mm/35 mm.
 - Hex socket head cap screws for mounting are provided with all products.
- *1: Stopper bolts are not provided. The customer is asked to prepare them.

• Application

Table position adjustment
Table retention and fall prevention
Stoppers for emergencies

• Material/Finish




	NLSEN
Main Body	SS400 Ferrosferric Oxide Film (Black)
Hex Socket Head Cap Screw	SCM435 Ferrosferric Oxide Film (Black)

Unit : mm

Part Number	W	H	A	S1	S2	P	T	M (Fine)		D	Hex Socket Head Cap Screw	Mass (g)
								Nominal of Thread	Pitch			
NLSEN-01	50	30	23.5	16	11	32	12	M6	0.75	5.5	M5×35	119.3
NLSEN-02	50	38	31.5	16	16	32	12	M6	0.75	5.5	M5×40	146.8
NLSEN-03	50	43	35.5	16	16	32	12	M6	0.75	5.5	M5×45	170.2
NLSEN-04	50	35	27.5	21	12	32	12	M8	1.0	5.5	M5×40	133.9
NLSEN-05	50	43	35.5	21	17	32	12	M8	1.0	5.5	M5×45	159.7
NLSEN-06	50	45	37.5	21	19	32	12	M8	1.0	5.5	M5×50	165
NLSEN-07	50	40	32.5	24	16	36	16	M8	1.0	6.6	M6×45	191.8
NLSEN-08	50	50	40.5	24	23	36	16	M8	1.0	6.6	M6×55	231.8
NLSEN-09	50	50	43.5	24	23	36	16	M8	1.0	6.6	M6×55	235
NLSEN-10	65	57	49.5	29	27	45	16	M8	1.0	9	M8×60	344.3
NLSEN-11	75	65	55.5	35	30	55	16	M8	1.0	9	M8×70	456.8

• Usage Example

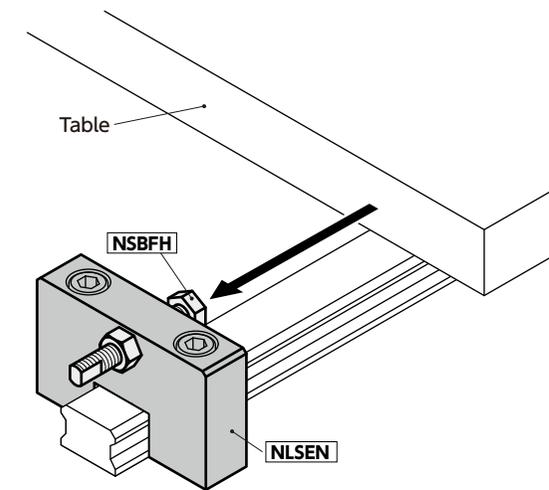

- Use the lock nut on the opposite side of the side that receives the force.



• Related Products

Stopper bolts **NSBFH** are available.

Rounded head type stopper bolts **NSBRH** are available.

Stopper bolts with urethane pad **NSBUH** are available.



• Part Number Specification

NLSEN-03



Cleanroom Wash & Packaging	Screw Combination	Screw Length Adjustment	Vibration Resistant	Laser Marking
Not Available	Not Available	Not Available	Not Available	Available / Add'l charge