




# SRTS Two Hole Pan Head Machine Screws

WEB Selection Tool  
 WEB CAD Download  
 Tamper Resistance  
 SUS Stainless steel

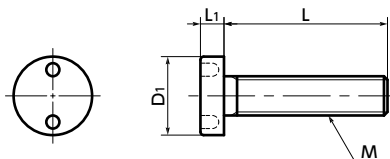

- Part number specification

## SRTS-M5-16



Order in number of packs.  
The minimum order is 1 piece. → P.xxxx

- This prevents mounting and removing with regular tools.
- Install and remove with **SRTB** Dedicated Bits and **SRD** Dedicated Magnetic Screwdriver together.
- The simple head design is suitable for decoration.

### • Application

Machinery / Tools / Equipment / Devices disassembly prevention / Tampering prevention / Theft prevention for outdoor facilities / Security measures / Safety measures

### • Material/Finish



	SRTS
Main Body	Equivalent to SUS304
Strength Class	Equivalent to A2-50

Unit : mm

Part Number	M (Coarse)		L							D1	L1	Bit Part No.	Screwdriver Part No.	Mass (g)
	Nominal of Thread	Pitch	6	8	10	12	16	20						
SRTS-M3	M3	0.5	6	8	10					6	1.8	SRTB-4	SRD-6.35	0.66 - 0.82
SRTS-M4	M4	0.7			10	12	16			8	2.4	SRTB-8	SRD-6.35	1.7 - 2.2
SRTS-M5	M5	0.8				12	16	20		10	3	SRTB-10	SRD-6.35	3.4 - 4.3

Part Number	L						Qty per Pack
	6	8	10	12	16	20	
SRTS-M3	●	●	●				20
SRTS-M4			●	●	●		20
SRTS-M5				●	●	●	20

• The minimum order is 1 piece. → P.xxxx

### • **SRTB** Dedicated Bit

Unit : mm


Part Number	L	B	Mass (g)	Qty per Pack
SRTB-4	25.4	6.35	5	1
SRTB-8	25.4	6.35	5	1
SRTB-10	25.4	6.35	5.2	1



### • **SRD** Dedicated Magnet Screwdriver

Unit : mm

Part Number	L	B	Mass (g)	Qty per Pack
SRD-6.35	210	6.35	98	1

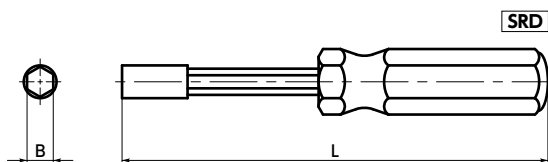

Individual Sales → P.xxxx  
 Cleanroom Wash & Packaging → P.xxxx  
 Screw Length Adjustment → P.xxxx  
 Vibration Resistant → P.xxxx  
 Modification process for captive use → P.xxxx

Available / Add'l charge   Available / Add'l charge   Available / Add'l charge   Available / Add'l charge   Available / Add'l charge