


SRHFS Hex Socket Flat Head Bolts (with Pin) NEW



WEB Selection Tool
WEB CAD Download
Tamper Resistance
SUS Stainless steel

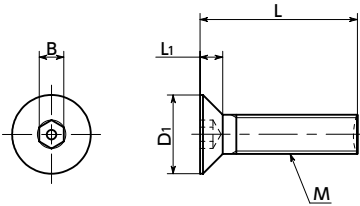

● Material/Finish



SRHFS	
Main Body	Equivalent to SUS304
Strength Class	Equivalent to A2-50

● Part number specification

SRHFS-M5 - 16



Order in number of packs.
The minimum order is 1 piece. → P.xxxx

- Flat head bolts with pin at the center of their socket.
- This prevents mounting and removing with regular tools.
- Use a dedicated wrench SRH for mounting and removing.

● Application

Machinery / Tools / Equipment / Devices disassembly prevention / Tampering prevention / Theft prevention for outdoor facilities / Security measures / Safety measures

Unit : mm

Part Number 1	M (Coarse)		L 2	D1	L1	B	Applicable Wrench	Mass (g)
	Nominal of Thread	Pitch						
SRHFS-M3	M3	0.5	6 8 10 12 16 20 25	6	1.75	2	SRH-2	0.53 - 1.4
SRHFS-M4	M4	0.7	8 10 12 16 20 25 30	8	2.3	2.5	SRH-2.5	1.2 - 2.9
SRHFS-M5	M5	0.8	8 10 12 16 20 25 30 40 50	10	2.8	3	SRH-3	2.3 - 7.4
SRHFS-M6	M6	1	10 12 16 20 25 30 35 40 50	12	3.4	4	SRH-4	3.9 - 12
SRHFS-M8	M8	1.25	10 12 16 20 25 30 35 40 50	16	4.7	5	SRH-5	9 - 23
SRHFS-M10	M10	1.5	25 30 40	18.3	5.6	6	SRH-6	19 - 29


Part Number	L											Qty per Pack
	6	8	10	12	16	20	25	30	35	40	50	
SRHFS-M3	●	●	●	●	●	●	●					10
SRHFS-M4		●	●	●	●	●	●	●				10
SRHFS-M5		●	●	●	●	●	●	●		●	●	10
SRHFS-M6			●	●	●	●	●	●	●	●	●	10
SRHFS-M8			●	●	●	●	●	●	●	●	●	10
SRHFS-M10							●	●		●		10

● The minimum order is 1 piece. → P.xxxx

● SRH Dedicated Wrench

Unit : mm

Part Number	B	L1	L2	Mass (g)	Qty per Pack
SRH-2	2	50	16	1.8	1
SRH-2.5	2.5	56	18	3.1	1
SRH-3	3	63	20	5	1
SRH-4	4	70	25	10	1
SRH-5	5	80	28	18	1
SRH-6	6	90	32	35	1

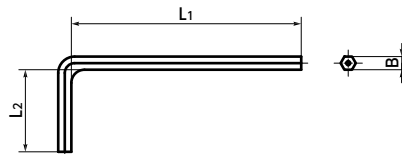

1 Individual Sales → P.xxxx
Cleanroom Wash & Packaging → P.xxxx
Screw Length Adjustment → P.xxxx
Vibration Resistant → P.xxxx
Modification process for captive use → P.xxxx

Available / Add'l charge Available / Add'l charge Available / Add'l charge Available / Add'l charge Not Available