


SRTRS Triangular Socket Button Head Cap Screws NEW



WEB Selection Tool
WEB CAD Download
Tamper Resistance
SUS Stainless steel

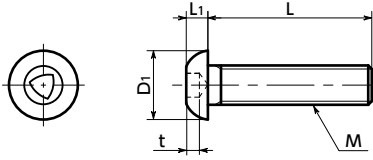

● Material/Finish RoHS2 Compliant

	SRTRS
本体	SUS304相当
強度区分	A2-50相当

● Part number specification

SRTRS-M5 - 16



Order in number of packs.
The minimum order is 1 piece. → P.xxxx

- Button head cap screws with triangular socket.
- This prevents mounting and removing with regular tools.
- Install and remove with **SRTRB** Dedicated Bits and **SRD** Dedicated Magnetic Screwdriver together.
- Application

Machinery / Tools / Equipment / Devices disassembly prevention/ Tampering prevention / Theft prevention for outdoor facilities / Security measures / Safety measures

Unit : mm

Part Number	M (Coarse)		L 2							D1	L1	t	Bit Part No.	Screwdriver Part No.	Mass (g)
	Nominal Thread	Pitch	6	8	10	12	16	20	25						
SRTRS-M3	M3	0.5	6	8	10	12	16	20		5.7	1.65	0.95	SRTRB-3	SRD-6.35	0.43 - 1.1
SRTRS-M4	M4	0.7	6	8	10	12	16	20		7.6	2.2	1.3	SRTRB-4	SRD-6.35	0.89 - 2
SRTRS-M5	M5	0.8			10	12	16	20	25	9.5	2.75	1.5	SRTRB-5	SRD-6.35	2.1 - 4.1
SRTRS-M6	M6	1		8	10	12	16	20	25	10.5	3.3	1.8	SRTRB-6	SRD-6.35	2.5 - 5.9


Part Number	L							Qty per Pack
	6	8	10	12	16	20	25	
SRTRS-M3	●	●	●	●	●	●		10
SRTRS-M4	●	●	●	●	●	●		10
SRTRS-M5			●	●	●	●	●	10
SRTRS-M6		●	●	●	●	●	●	10

● The minimum order is 1 piece. → P.xxxx

● **SRTRB** Dedicated bit

Unit : mm


Part Number	L	B	Mass (g)	Qty per Pack
SRTRB-3	32	6.35	5.8	1
SRTRB-4	32	6.35	6.4	1
SRTRB-5	32	6.35	6.5	1
SRTRB-6	32	6.35	7	1

 

● **SRD** Dedicated magnet screwdriver

Unit : mm

Part Number	L	B	Mass (g)	Qty per Pack
SRD-6.35	210	6.35	98	1

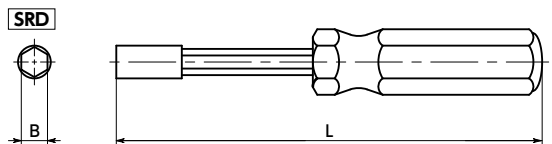

Individual Sales → P.xxxx
Cleanroom Wash & Packaging → P.xxxx
Screw Length Adjustment → P.xxxx
Vibration Resistant → P.xxxx
Modification process for captive use → P.xxxx