




# SNSS-FT Hex Socket Head Cap Screws - Full Thread

WEB Selection Tool

WEB CAD Download

SUS Stainless steel

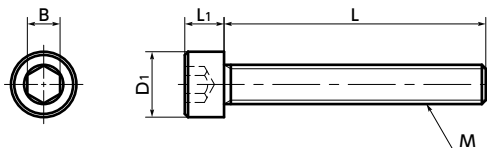

● Full thread socket head cap screws.

● Application

Equipment and devices that require long screws

● Material/Finish

RoHS2 Compliant

	SNSS-FT
Main Body	SUSXM7 (Equivalent to SUS304)
Strength Class	A2-50

Unit : mm

Part Number	M (Coarse)		L																D1	L1	B	Mass (g)	
	Nominal of Thread	Pitch	25	30	35	40	45	50	55	60	65	70	75	80	85	90	100	110					120
SNSS-M3-FT	M3	0.5																		5.5	3	2.5	1.6 - 2.9
SNSS-M4-FT	M4	0.7																		7	4	3	3.7 - 11
SNSS-M5-FT	M5	0.8																		8.5	5	4	5.6 - 16
SNSS-M6-FT	M6	1																		10	6	5	9.9 - 24
SNSS-M8-FT	M8	1.25																		13	8	6	21 - 45
SNSS-M10-FT	M10	1.5																		16	10	8	36 - 84

Part Number	Qty per pack
SNSS-M3-FT	1
SNSS-M4-FT	1
SNSS-M5-FT	1
SNSS-M6-FT	1
SNSS-M8-FT	1
SNSS-M10-FT	1

## ● Related Products

**SSH-FT** Low Profile Screws (Hex Socket Head Cap Screws with Low Profile Full Thread)

➔ P.xxxx



**SPE-FT** Plastic Screw (PEEK / Hex Socket Head Cap Screws - Full Thread)

➔ P.xxxx



● Part number specification

**SNSS-M3-25-FT**

Product Code **1** **2** Product Code

Individual Sales ➔ P.xxxx	Cleanroom Wash & Packaging ➔ P.xxxx	Screw Length Adjustment ➔ P.xxxx	Vibration Resistant ➔ P.xxxx	Modification process for captive use ➔ P.xxxx
1 unit in 1 bag	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Not Available