




SNHS-LH Hex Head Screw / Special Low Head

WEB Selection Tool
 WEB CAD Download
 Protrusion
 SUS Stainless steel

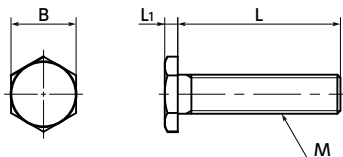

- Hexagon Head Bolt with low head.
- For space-saving of equipment/device and applications with a limited top space.

● Application

Reducing the size of equipment and devices

● Material/Finish

RoHS2 Compliant

SNHS-LH	
Main body	Equivalent to SUS304

Unit : mm

Part Number	M (Coarse)		L	L1	B	Mass (g)
	Nominal of Thread	Pitch				
SNHS-M4-LH	M4	0.7	8 10 12 15 20 25 30	1.5	7	1.2 - 2.9
SNHS-M5-LH	M5	0.8	8 10 12 15 20 25 30	2	8	1.9 - 4.7
SNHS-M6-LH	M6	1	10 12 15 20 25 30	2	10	3.2 - 6.9
SNHS-M8-LH	M8	1.25	15 20 25 30	2	13	7.8 - 12

Part Number	Qty per pack
SNHS-M4-LH	10
SNHS-M5-LH	10
SNHS-M6-LH	10
SNHS-M8-LH	10

● Also sold separately from 1 piece up. → P.xxxx

● Part number specification

SNHS - M5 - 25 - LH

Product Code Product Code

Place order by a bag.

Also sold separately from 1 piece up. → P.xxxx

Individual Sales → P.xxxx	Cleanroom Wash & Packaging → P.xxxx	Screw Length Adjustment → P.xxxx	Vibration Resistant → P.xxxx	Modification process for captive use → P.xxxx
Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge	Available / Add'l charge