


LKP リニアクランプ・ズィー - 空気圧 - 常時開 - スリムタイプ 品番変更 仕様変更

空気圧タイプ N/O 常時開

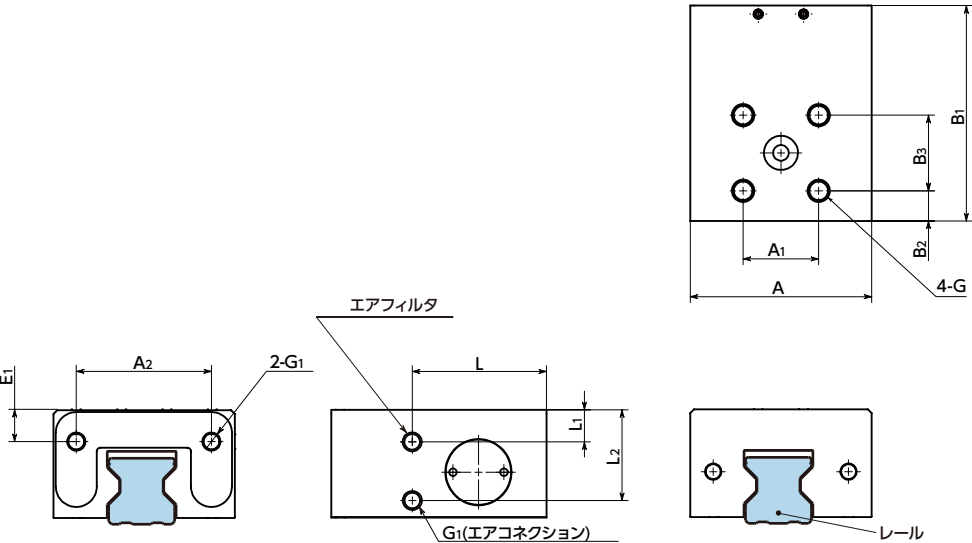

●クランプ部の形状は品番により異なります。各品番の形状は、CADデータをご確認ください。

寸法・性能

単位：mm

品番 	保持力*1 (N)	A	A1	A2	B1	B2	B3	E1	G/深さ	G1	L	L1	L2	質量 (kg)
LKP-1501-AS2-A	550	34	15	22	49	8.5	15	5	M4/4.5	M3	31.5	4.5	17	0.15
LKP-1502-BS2-A	550	34	15	22	49	8.5	15	5	M4/4.5	M3	31.5	4.5	17	0.15
LKP-1505-AS2-A	550	34	15	22	49	8.5	15	5	M4/4.5	M3	31.5	4.5	17	0.15
LKP-2001-AS2-A	850	44	20	32	52	7	20	7	M5/5.5	M3	33.5	4.5	20.5	0.23
LKP-2002-BS2-A	850	44	20	32	52	7	20	7	M5/5.5	M3	33.5	4.5	20.5	0.23
LKP-2005-AS2-A	850	44	20	32	52	7	20	7	M5/5.5	M3	33.5	4.5	20.5	0.23
LKP-2014-DS2-A	1100	44	20	32	52	7	20	7	M5/5.5	M3	33.5	4.5	20.5	0.23
LKP-2501-AS2-A	1100	48	20	35.75	57	8	20	8.5	M6/6.0	M5	35.5	8.5	24	0.33
LKP-2502-BS2-A	1100	48	20	35.75	57	8	20	8.5	M6/6.0	M5	35.5	8.5	24	0.33
LKP-2502-DS2-A	1100	48	20	35.75	57	8	20	8.5	M6/6.0	M5	35.5	8.5	24	0.33
LKP-2504-FS2-A	1100	48	20	35.75	57	8	20	8.5	M6/6.0	M5	35.5	8.5	24	0.33
LKP-2505-AS2-A	1100	48	20	35.75	57	8	20	8.5	M6/6.0	M5	35.5	8.5	24	0.33
LKP-2505-BS2-A	1100	48	20	35.75	57	8	20	8.5	M6/6.0	M5	35.5	8.5	24	0.33
LKP-2514-DS2-A	1100	48	20	35.75	57	8	20	8.5	M6/6.0	M5	35.5	8.5	24	0.33
LKP-3001-AS2-A	1800	60	22	44.3	66.5	8.5	22	10	M8/8.5	M5	41.5	6.5	30	0.57
LKP-3001-ES2-A	1800	60	22	44.3	66.5	8.5	22	10	M8/8.5	M5	41.5	6.5	30	0.57
LKP-3002-BS2-A	1800	60	22	44.3	66.5	8.5	22	10	M8/8.5	M5	41.5	6.5	30	0.57
LKP-3004-FS2-A	1800	60	22	44.3	66.5	8.5	22	10	M8/8.5	M5	41.5	6.5	30	0.57
LKP-3005-AS2-A	1800	60	22	44.3	66.5	8.5	22	10	M8/8.5	M5	41.5	6.5	30	0.57
LKP-3012-FS2-A	1800	60	22	44.3	66.5	8.5	22	10	M8/8.5	M5	41.5	6.5	30	0.57
LKP-3014-DS2-A	1800	60	22	44.3	66.5	8.5	22	10	M8/8.5	M5	41.5	6.5	30	0.57
LKP-3014-ES2-A	1800	60	22	44.3	66.5	8.5	22	10	M8/8.5	M5	41.5	6.5	30	0.57
LKP-3501-AS2-A	2500	70	24	52.3	68.5	7.5	24	12	M8/10.0	M5	41.5	7.5	35.5	0.78
LKP-3501-ES2-A	2500	70	24	52.3	68.5	7.5	24	12	M8/10.0	M5	41.5	7.5	35.5	0.79

*1：圧力が0.6MPaのときの値です。保持力は0.3MPa～0.6MPaの範囲では圧力に比例します。

● 品番指定 ※価格・納期はNBKウェブサイトをご覧ください。

LKP-2501-AS2-A



 レバー位置変更

対応不可

単位：mm

品番 	保持力*1 (N)	A	A1	A2	B1	B2	B3	E1	G/深さ	G1	L	L1	L2	質量 (kg)
LKP-3502-AS2-A	2500	70	24	52.3	68.5	7.5	24	12	M8/10.0	M5	41.5	7.5	35.5	1.1
LKP-3502-BS2-A	2500	70	24	52.3	68.5	7.5	24	12	M8/10.0	M5	41.5	7.5	35.5	0.78
LKP-3502-DS2-A	2500	70	24	52.3	68.5	7.5	24	12	M8/10.0	M5	41.5	7.5	35.5	1.1
LKP-3503-AS2-A	2500	70	24	52.3	68.5	7.5	24	12	M8/10.0	M5	41.5	7.5	35.5	0.87
LKP-3504-FS2-A	2500	70	24	52.3	68.5	7.5	24	12	M8/10.0	M5	41.5	7.5	35.5	0.87
LKP-3505-AS2-A	2500	70	24	52.3	68.5	7.5	24	12	M8/10.0	M5	41.5	7.5	35.5	1.1
LKP-3505-BS2-A	2500	70	24	52.3	68.5	7.5	24	12	M8/10.0	M5	41.5	7.5	35.5	1.1
LKP-3510-BS2-A	2500	70	24	52.3	68.5	7.5	24	12	M8/10.0	M5	41.5	7.5	35.5	0.87
LKP-3512-FS2-A	2500	70	24	52.3	68.5	7.5	24	12	M8/10.0	M5	41.5	7.5	35.5	0.78
LKP-3514-ES2-A	2500	70	24	52.3	68.5	7.5	24	12	M8/10.0	M5	41.5	7.5	35.5	0.78
LKP-4501-AS2-A	3500	86	26	66.2	78	11	26	15	M10/12.0	M5	46	9	45	1.7
LKP-4501-ES2-A	3500	86	26	66.2	78	11	26	15	M10/12.0	M5	46	9	45	1.7
LKP-4502-AS2-A	3500	86	26	66.2	78	11	26	15	M10/12.0	M5	46	9	45	1.7
LKP-4502-BS2-A	3500	86	26	66.2	78	11	26	15	M10/12.0	M5	46	9	45	1.3
LKP-4502-DS2-A	3500	86	26	66.2	78	11	26	15	M10/12.0	M5	46	9	45	1.7
LKP-4503-AS2-A	3500	86	26	66.2	78	11	26	15	M10/12.0	M5	46	9	45	1.7
LKP-4504-FS2-A	3500	86	26	66.2	78	11	26	15	M10/12.0	M5	46	9	45	1.7
LKP-4505-AS2-A	3500	86	26	66.2	78	11	26	15	M10/12.0	M5	46	9	45	1.3
LKP-4505-BS2-A	3500	86	26	66.2	78	11	26	15	M10/12.0	M5	46	9	45	1.7
LKP-4514-ES2-A	3500	86	26	66.2	78	11	26	15	M10/12.0	M5	46	9	45	1.3
LKP-5501-AS2-A	4500	100	30	77.2	78	9	30	15	M10/14.0	M5	46	10	51	2.2
LKP-5501-ES2-A	4500	100	30	77.2	78	9	30	15	M10/14.0	M5	46	10	51	2.3
LKP-5502-AS2-A	4500	100	30	77.2	78	9	30	15	M10/14.0	M5	46	10	51	2.3
LKP-5502-BS2-A	4500	100	30	77.2	78	9	30	15	M10/14.0	M5	46	10	51	2.3
LKP-5503-AS2-A	4500	100	30	77.2	78	9	30	15	M10/14.0	M5	46	10	51	1.7
LKP-5505-AS2-A	4500	100	30	77.2	78	9	30	15	M10/14.0	M5	46	10	51	2.3
LKP-5505-BS2-A	4500	100	30	77.2	78	9	30	15	M10/14.0	M5	46	10	51	1.7
LKP-5512-FS2-A	4500	100	30	77.2	78	9	30	15	M10/14.0	M5	46	10	51	2.3
LKP-5514-ES2-A	4500	100	30	77.2	78	9	30	15	M10/14.0	M5	46	10	51	2.3

*1：圧力が0.6MPaのときの値です。保持力は0.3MPa～0.6MPaの範囲では圧力に比例します。