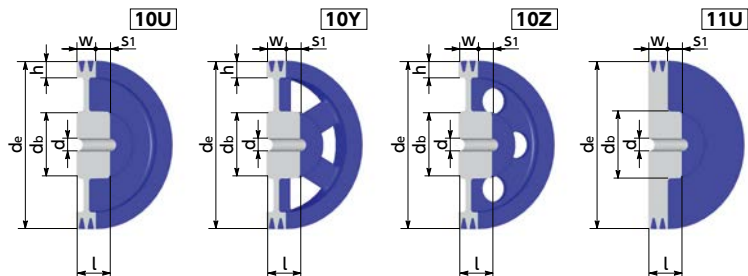


5V-2 ウェッジプーリー - 5V・5VX適用

[WEB 選定ナビ](#) [WEB CAD Download](#)


単位: mm

品番	価格 (円)	ピッチ径 dp	外径 de	最大軸穴径 d	下穴径 d	形状 図番	ハブ				リム		慣性モーメント (kg・m ²)	質量 (kg)
							db	l	s1	s2	w	h ⁺³ ₀		
112-5V-2	5,710	109.4	113	45	-	11U	80	55	12.1	-	42.9	-	0.0036	2.94
118-5V-2	6,640	115.4	119	50	-	11U	90	55	12.1	-	42.9	-	0.00464	3.36
125-5V-2	7,250	122.4	126	50	-	11U	90	55	12.1	-	42.9	-	0.0058	3.75
132-5V-2	7,730	129.4	133	50	-	11U	90	55	12.1	-	42.9	-	0.00718	4.15
140-5V-2	8,130	137.4	141	50	-	11U	90	55	12.1	-	42.9	-	0.00909	4.65
150-5V-2	8,250	147.4	151	50	-	11U	90	55	12.1	-	42.9	-	0.012	5.31
160-5V-2	8,710	157.4	161	50	-	11U	90	55	12.1	-	42.9	-	0.0157	6.02
170-5V-2	9,440	167.4	171	60	-	11U	100	55	12.1	-	42.9	-	0.0205	6.92
180-5V-2	9,790	177.4	181	60	-	11U	100	55	12.1	-	42.9	-	0.0259	7.74
190-5V-2	11,000	187.4	191	55	-	10U	100	55	12.1	-	42.9	23.5	0.0248	6.65
200-5V-2	11,500	197.4	201	55	-	10U	100	55	12.1	-	42.9	23.5	0.0339	7.29
210-5V-2	11,700	207.4	211	55	-	10U	100	55	12.1	-	42.9	22.5	0.0347	7.41
212-5V-2	11,700	209.4	213	55	-	10U	100	55	12.1	-	42.9	23.5	0.0363	7.59
220-5V-2	12,300	217.4	221	55	-	10U	100	55	12.1	-	42.9	21.5	0.0401	7.81
224-5V-2	12,600	221.4	225	55	-	10U	100	55	12.1	-	42.9	23.5	0.0427	7.85
230-5V-2	12,900	227.4	231	55	-	10U	100	60	17.1	-	42.9	20.5	0.0461	8.42
236-5V-2	13,200	233.4	237	55	-	10U	100	60	17.1	-	42.9	23.5	0.0542	9.09
240-5V-2	14,200	237.4	241	55	-	10U	100	60	17.1	-	42.9	23.5	0.0576	9.28
250-5V-2	14,700	247.4	251	65	-	10U	110	60	17.1	-	42.9	23.5	0.0681	10.3
260-5V-2	15,700	257.4	261	65	-	10U	110	60	17.1	-	42.9	21	0.0747	10.5
265-5V-2	15,900	262.4	266	65	-	10U	110	60	17.1	-	42.9	23.5	0.0846	11.2
280-5V-2	16,600	277.4	281	65	-	10U	110	60	17.1	-	42.9	23.5	0.103	12
300-5V-2	17,700	297.4	301	65	-	10Z	110	60	17.1	-	42.9	23.5	0.121	11.9
315-5V-2	19,400	312.4	316	65	-	10Z	110	65	22.1	-	42.9	23.5	0.144	12.9
335-5V-2	21,000	332.4	336	65	-	10Z	110	65	22.1	-	42.9	23.5	0.176	13.5
355-5V-2	23,100	352.4	356	65	-	10Z	110	65	22.1	-	42.9	23.5	0.213	14.1
375-5V-2	25,200	372.4	376	65	-	10Z	110	65	22.1	-	42.9	23.5	0.26	15.1
400-5V-2	27,000	397.4	401	75	-	10Z	130	65	22.1	-	42.9	23.5	0.331	18
450-5V-2	35,500	447.4	451	75	-	10Z	130	70	27.1	-	42.9	23.5	0.57	24.1
500-5V-2	42,500	497.4	501	75	-	10Z	130	70	27.1	-	42.9	23.5	0.829	27.3
530-5V-2	49,400	527.4	531	85	35	10Z	150	80	37.1	-	42.9	23.5	1.12	35.4
630-5V-2	55,900	627.4	631	85	35	10Y	150	80	37.1	-	42.9	23.5	1.33	30.8

追加工サービスをご利用ください。

Vプーリーに軸穴・キー溝・押しねじ穴の
追加工をいたします。実働1日日出荷。

→ P.xxxx



● 軸穴・キー溝・押しねじ追加工 → P.xxxx

対応可・別料金

● 品番指定

直送 14時当日出荷 [WEB NBK ネットショップ](#)

150-5V-2

1