


5V-3 ウェッジプーリー - 5V・5VX適用


WEB 選定ナビ WEB CAD Download

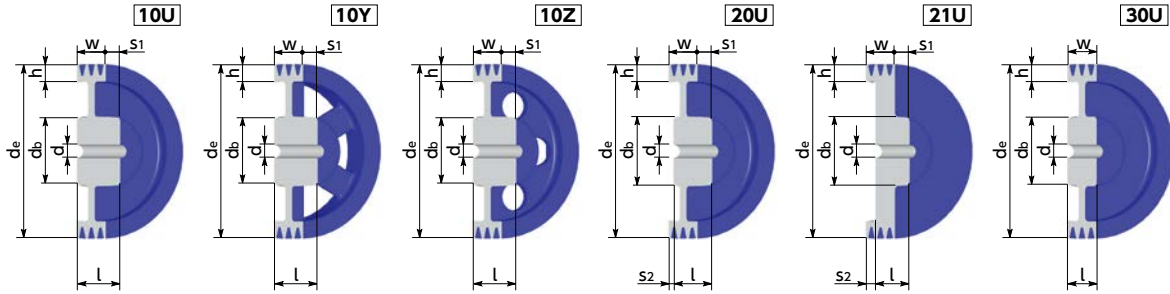

単位:mm

品番	価格 (円)	ピッチ径 dp	外径 de	最大軸穴径 d	下穴径 d	形状図番	ハブ				リム		慣性モーメント (kg・m ²)	質量 (kg)
							db	l	s1	s2	w	h ⁺³ ₀		
112-5V-3	6,960	109.4	113	45	-	31U	-	60.4	-	-	60.4	-	0.00438	3.42
118-5V-3	8,420	115.4	119	50	-	31U	-	60.4	-	-	60.4	-	0.00551	3.85
125-5V-3	8,570	122.4	126	50	-	31U	-	60.4	-	-	60.4	-	0.00709	4.38
132-5V-3	9,080	129.4	133	55	-	31U	-	60.4	-	-	60.4	-	0.009	4.95
140-5V-3	9,390	137.4	141	60	-	31U	-	60.4	-	-	60.4	-	0.0116	5.64
150-5V-3	10,100	147.4	151	65	-	31U	-	60.4	-	-	60.4	-	0.0157	6.57
160-5V-3	11,200	157.4	161	60	-	21U	100	65	14.6	10	60.4	25.5	0.0207	7.72
170-5V-3	12,500	167.4	171	60	-	21U	100	65	14.6	10	60.4	25.5	0.0265	8.66
180-5V-3	12,600	177.4	181	60	-	21U	100	70	14.6	5	60.4	25.5	0.0337	9.94
180-5V-3F	13,200	177.4	181	85	-	31U	-	60.4	-	-	60.4	-	0.0343	9.77
190-5V-3	13,900	187.4	191	60	-	21U	100	70	14.6	5	60.4	25.5	0.0429	11.3
190-5V-3F	14,600	187.4	191	90	-	31U	-	60.4	-	-	60.4	-	0.0433	11
200-5V-3	14,300	197.4	201	60	-	21U	100	70	14.6	5	60.4	25.5	0.053	12.5
200-5V-3F	14,700	197.4	201	55	-	30U	100	60.4	-	-	60.4	25.5	0.04	8.85
210-5V-3	14,400	207.4	211	55	-	20U	100	70	14.6	5	60.4	24.5	0.0469	9.75
212-5V-3	15,000	209.4	213	55	-	20U	100	70	14.6	5	60.4	25.5	0.0496	10
212-5V-3F	15,800	209.4	213	55	-	30U	100	60.4	-	-	60.4	25.5	0.0488	9.46
220-5V-3	16,400	217.4	221	70	-	10U	120	70	9.6	-	60.4	23.5	0.0601	11.9
224-5V-3	16,500	221.4	225	70	-	10U	120	70	9.6	-	60.4	25.5	0.0649	12.2
230-5V-3	16,600	227.4	231	70	-	10U	120	70	9.6	-	60.4	22.5	0.0658	12
236-5V-3	17,000	233.4	237	70	-	10U	120	70	9.6	-	60.4	25.5	0.0771	12.9
240-5V-3	18,000	237.4	241	70	-	10U	120	70	9.6	-	60.4	25.5	0.0815	13.1
250-5V-3	18,500	247.4	251	70	-	10U	120	70	9.6	-	60.4	22.5	0.0935	13.7
260-5V-3	19,900	257.4	261	75	-	10U	130	70	9.6	-	60.4	23	0.105	15.7
265-5V-3	20,300	262.4	266	75	-	10U	130	70	9.6	-	60.4	25.5	0.118	15.5
280-5V-3	20,400	277.4	281	75	-	10U	130	70	9.6	-	60.4	25.5	0.143	16.5

単位:mm

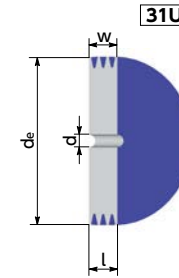

品番	価格 (円)	ピッチ径 dp	外径 de	最大軸穴径 d	下穴径 d	形状図番	ハブ				リム		慣性モーメント (kg・m ²)	質量 (kg)
							db	l	s1	s2	w	h ⁺³ ₀		
300-5V-3	21,800	297.4	301	75	-	10Z	130	80	19.6	-	60.4	25.5	0.172	17.7
315-5V-3	24,900	312.4	316	80	-	10Z	140	80	19.6	-	60.4	25.5	0.209	19.8
335-5V-3	28,700	332.4	336	80	-	10Z	140	80	19.6	-	60.4	25.5	0.257	21.1
355-5V-3	31,400	352.4	356	80	-	10Z	140	80	19.6	-	60.4	25.5	0.313	22.4
375-5V-3	34,400	372.4	376	80	-	10Z	140	80	19.6	-	60.4	25.5	0.378	23.7
400-5V-3	37,100	397.4	401	85	35	10Z	150	90	29.6	-	60.4	25.5	0.482	27.3
425-5V-3	41,400	422.4	426	85	35	10Z	150	90	29.6	-	60.4	25.5	0.593	29
450-5V-3	45,300	447.4	451	85	35	10Z	150	90	29.6	-	60.4	25.5	0.776	33.2
475-5V-3	48,500	472.4	476	85	35	10Z	150	90	29.6	-	60.4	25.5	0.898	33.9
500-5V-3	52,300	497.4	501	85	35	10Z	150	90	29.6	-	60.4	25.5	1.13	37.3
530-5V-3	58,100	527.4	531	85	35	10Z	150	95	34.6	-	60.4	25.5	1.35	39.7
560-5V-3	63,400	557.4	561	85	35	10Z	150	95	34.6	-	60.4	25.5	1.67	42.9
600-5V-3	66,800	597.4	601	90	48	10Z	160	95	34.6	-	60.4	25.5	2.16	48.3
630-5V-3	73,800	627.4	631	90	48	10Y	160	95	34.6	-	60.4	25.5	1.98	43
710-5V-3	88,500	707.4	711	90	48	10Y	160	95	34.6	-	60.4	25.5	2.95	49.6
750-5V-3	94,900	747.4	751	95	48	10Y	170	100	39.6	-	60.4	25.5	3.59	55.9
800-5V-3	104,000	797.4	801	95	48	10Y	170	100	39.6	-	60.4	25.5	4.38	59.2
900-5V-3	134,000	897.4	901	95	48	10Y	170	105	44.6	-	60.4	25.5	6.44	68.3
1000-5V-3	188,000	997.4	1001	95	48	10Y	170	105	44.6	-	60.4	25.5	9.42	80.5

追加工サービスをご利用ください。

Vプーリーに軸穴・キー溝・押しねじ穴の追加工をいたします。実働1日日出荷。

➔ P.xxxx



● 軸穴・キー溝・押しねじ追加工 ➔ P.xxxx

対応可・別料金

● 品番指定

180-5V-3

1

直送 14時当日出荷 WEB NBKネットショップ

● 関連商品

プーリーV溝部の摩耗を確認するためのゲージがあります。プーリーのメンテナンスの際に、ご利用ください。

➔ P.xxxx

